



INHEX socket

59

Product no. **05050014**
GTIN **4018754009282**
Model **59 14**




Label. INHEX socket 3/4 " 14mm L.80mm

Properties.

- for hex socket head screws
- 3/4" internal square drive
- Chrome Alloy Steel, chrome-plated
- DIN 7422

Technical drawing.

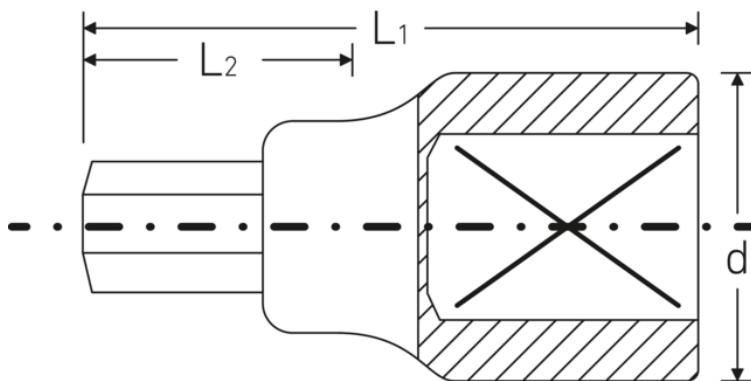

Technical attributes.

Drive profile	hex
External hex drive (mm)	14 mm
Internal square drive (inch)	3/4 "
d	34,7 mm
DIN	DIN 7422

Logistics data.

Depth mm (IFS)	80
Width mm (IFS)	35
Height mm (IFS)	35
WEEE/ElektroG	nicht ear-pflichtig
Length (packed, mm)	80

L1	80 mm	Width (packed, mm)	35
L2	25 mm	Height (packed, mm)	35
		Volume (packed, dm3)	0.098 dm3
		Art. no.	05050014
		Weight (gross, kg)	0,280
		Weight PAP (kg)	0,000
		Weight PVC (kg)	0,003
		GTIN	4018754009282
		Country of origin AWR	GERMANY
		Region of origin	Nordrhein-Westfalen
		Customs tariff no.	82042000
		Packing standard	1
		Weight	272 g

Variants.

Art. no.	Model no. (ERP)	Description	GTIN
05050014	59 14	INHEX socket 3/4 " 14mm L.80mm	4018754009282
05050017	59 17	INHEX socket 3/4 " 17mm L.80mm	4018754009299
05050019	59 19	INHEX socket 3/4 " 19mm L.80mm	4018754009305
05050022	59 22	INHEX socket 3/4 " 22mm L.80mm	4018754132164

GTIN.



STAHLWILLE Eduard Wille GmbH & Co. KG

Lindenallee 27 · 42349 Wuppertal · Germany · Phone: +49 202 4791-0 · Fax: +49 202 4791-200
info@stahlwille.de · www.stahlwille.com · Copyright by STAHLWILLE Eduard Wille GmbH & Co. KG, Wuppertal
Copyright by STAHLWILLE Eduard Wille GmbH & Co. KG, Wuppertal