



## Model No. M50EURD

80mm wide Excell® stainless steel discus padlock with shrouded shackle

### Best Used For:



Self-Storage Units & Lockers

 


Sheds, Workshops & Garages



Trailers, Vans & Moving Trucks

### Security Level:



High to maximum security:

Recommended for all use including industrial applications

## Overview & Features

## Product Features


- Tough-Cut® octagonal boron-carbide shackle is 50% harder than hardened steel
- 80mm wide stainless steel body construction for maximum weather resistance
- Fully shrouded design minimizes shackle exposure and protects against bolt cutter attacks
- Reinforced body bumper for scratch resistance
- 4-pin cylinder for increased pick resistance
- Covered keyway for maximum weather protection
- Key retaining feature ensures padlock is not left unlocked
- Limited Lifetime Warranty

## Product Details

The Master Lock Excell® No. M50EURD Discus Padlock features a 80mm wide stainless steel body for maximum strength, reliability and corrosion resistance. The fully shrouded design minimizes shackle exposure and protects against bolt cutter attacks. The 12mm diameter octagonal shackle is 17mm long and made of Tough-Cut™ boron-carbide, 50% harder than hardened steel, offering maximum resistance to cutting and sawing. The 4-pin cylinder prevents picking and the dual locking ball bearings provide maximum resistance against prying and hammering. The covered keyway offers maximum weather protection, and reinforced body bumper protects against scratches. The Limited Lifetime Warranty provides peace of mind from a brand you can trust.

Product Specifications

Product Number	M50EURD
Body Width	80mm
Shackle Dimensions	A: 12 mm B: 17 mm C: 24 mm
Colour	Silver
Description	Keyed Alike
Shelf Pack Qty	4
Master Carton Qty	24

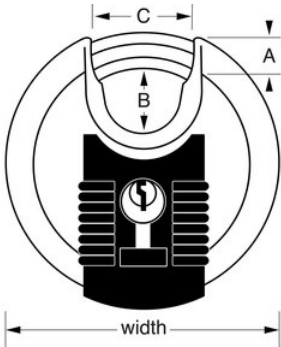

Master Lock Europe S.A.S.

10 avenue de l'arche - Le Colisée Gardens, bâtiment A - 92 400 Courbevoie - La Défense - France  
O:+33-1-41437200 | F:+33-1-41437204  
[www.masterlock.eu](http://www.masterlock.eu)