



MASTERColour CDM-R Mini 20W/830 GX10 MR16 25D 1CT

Product family description

The easy way to reflect more sparkle
The new Philips MASTERColour CDM-R mini brings trusted MASTERColour quality to 50mm reflector lamps with the superior output and colour stability to create the right atmosphere to match your customers' retail brand and positioning

Product Features

- Miniaturized 50mm CDM reflector lamp
- High beam intensity
- Long lamp lifetime compared to halogen lamps
- Twist and lock system

Product Benefits

- The miniaturized 50mm CDM reflector lamp makes it possible to use the smaller fixtures and has less clutter in the ceiling
- Suitable for open luminaires, Easy installation and easy maintenance
- Saves up to 60% energy compared to low voltage halogen lamps. Relatively low heat output
- This lamp gives the crisp white lighting effect with excellent colour stability

Environment

- Good environmental choice because of high energy efficiency and long reliable life
- The product is certified by Philips Green Flagship
- The product is RoHS compliant
- The product is covered by WEEE

Application

- Miniaturized crisp white light system for superior accent and general lighting in shops

Luminaires

- 50mm reflector design increases flexibility in application, and allows easy adaptation of halogen low voltage reflector luminaires
- Suitable in open luminaires
- Recommend to use ceramic lamp holders



System

- It is recommended to use Philips HID PrimaVision Mini Gear for optimal performance, but any other electronic gear suitable for GX10 compact HID lamps can also be used

Product data	
Order code	800036 00
Full product code	872790080003600
loccod	
Full product name	MASTERCcolour CDM-R Mini 20W/830 GX10 MR16 25D 1CT
Order product name	MASTERC CDM-Rm 20W/830 GX10 MR16 25D 1CT
Packing type	1 Lamp in a Folding Carton
Pieces per pack	1
Packing configuration	6
Packs per outerbox	6
Bar code on pack - EAN1	8727900800036
Bar code on intermediate packing - EAN2	
Bar code on outerbox - EAN3	8727900800043
Logistic code(s) - 12NC	
ILCOS code	MRS/UB-20/30/1B-H-GX10
Net weight per piece	0.050 KG
Successor order code	
Cap-Base	GX10
Bulb	MR16 [MR 16inch/50mm]
Bulb Finish	-
Burning Position	any [Any/Universal]
Life to 5% failures	6000 hr
Life to 10% failures	7000 hr
Life to 20% failures	8000 hr
Life to 50% failures	12000 hr
Rated Lamp Wattage	20W
Lamp Wattage EM	- W
Lamp Wattage EL	22 W
Lamp Voltage	103 V
Lamp Current EM	- A
Lamp Current EL	0.215 A
Dimmable	no
Mercury (Hg) Content	2.4 mg
Beam Description	-
Beam Angle	25D
Luminous Intensity	3500 cd
Colour Code	830 [CCT of 3000K]
Colour Rendering Index	87 Ra8
Colour Temperature	3000 K
Chromaticity Coordinate X	434 -
Chromaticity Coordinate Y	395 -
Lamp Luminous Flux EM	- Lm
Lamp Luminous Flux EL	1060 Lm
Cap-Base Temperature	200 C
Bulb Temperature	300 C




MASTERC CDM-Rm GX10 MR16 25D/40D

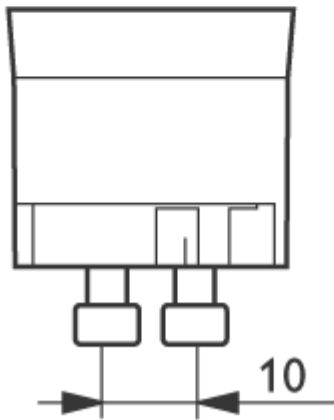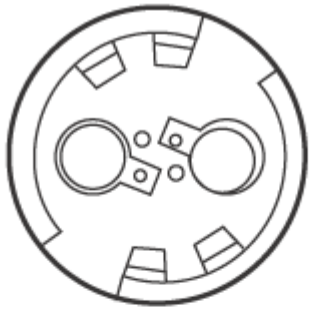



Cap-Base GX10



asimpleswitch.com

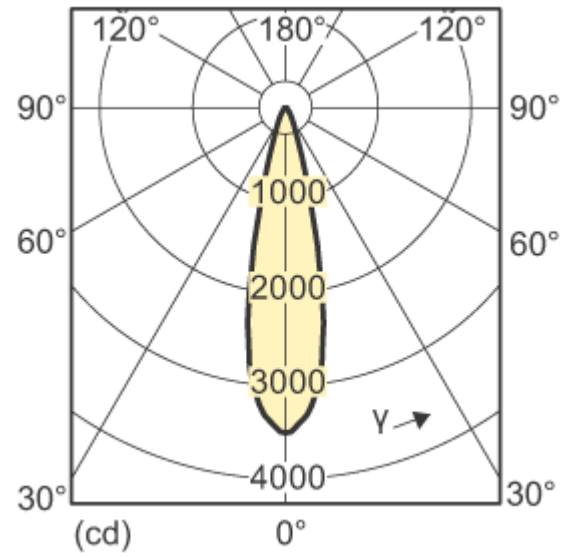


MASTERC CDM-Rm 20W/830 25D

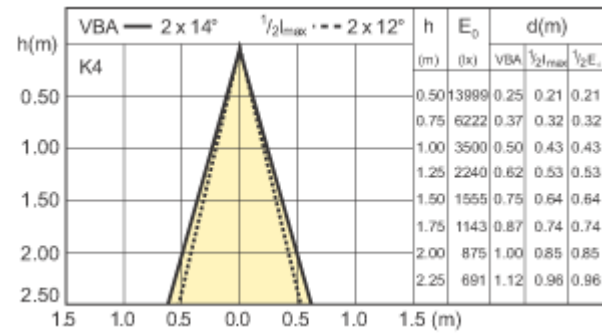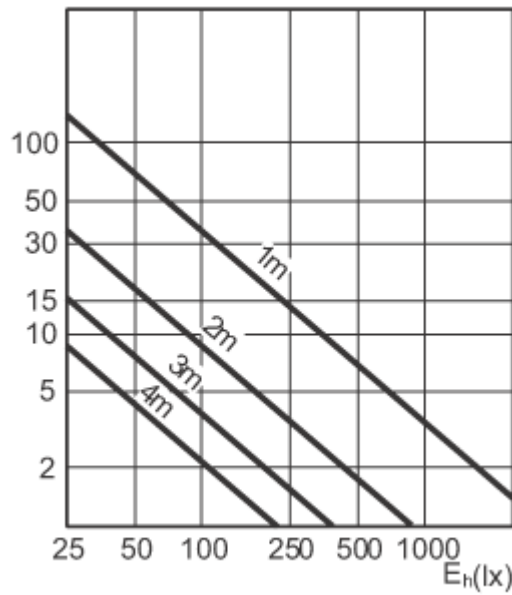


MASTERC CDM-Rm 20W/830 25D

MASTERC CDM-Rm 20W/830 25D

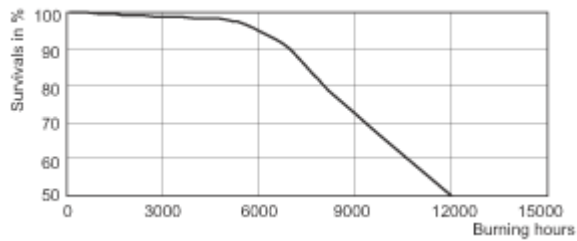


MASTERC CDM-Rm 20W/830

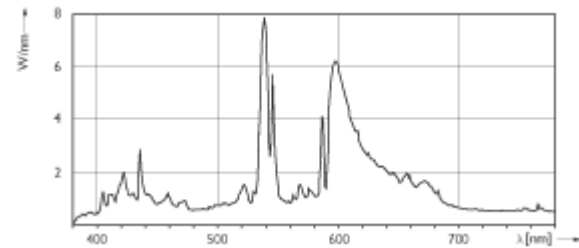


MASTERColour CDM-R Mini /830

MASTERC CDM-Rm/830

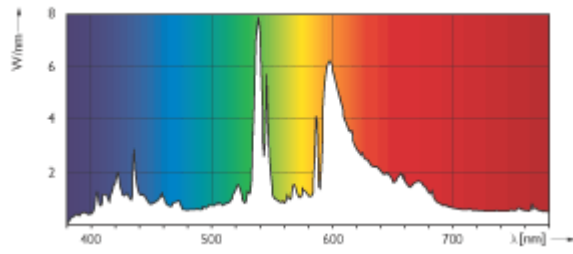


MASTERColour CDM-R Mini /830


MASTERC CDM-Rm/830

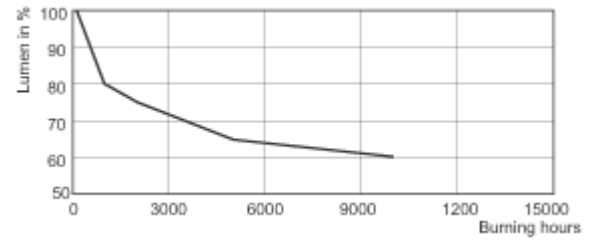

MASTERC CDM-Rm 20W/830

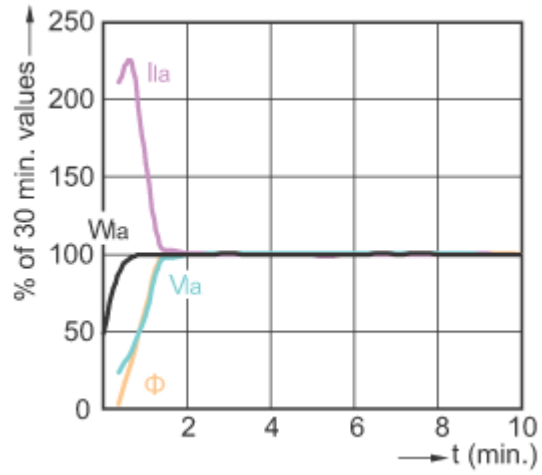

MASTERC CDM-Rm 20W/830

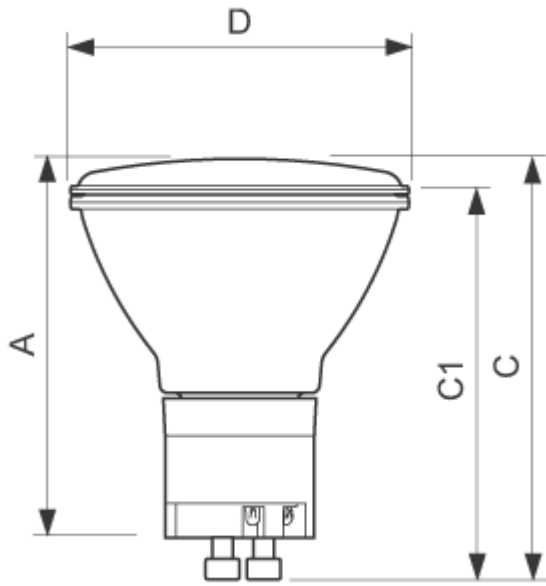

MASTERColour CDM-Rm GX10

	A	C1
Full product name	Max	Max
MASTERColour CDM-R Mini 20W/ 830 GX10 MR16 25D 1CT	59	60.9

