

## CL A HAL ECO PRO 116 W 230 V E27

---

HALOGEN ECO PRO CLASSIC A | Halogen lamps, classic bulb shape



- General illumination
- Mood lighting
- Entrance lighting
- Restaurants, hotels and similar prestigious applications

### Product benefits

---

- Simple direct replacement for conventional incandescent lamps
- The same pleasant quality of light as that of an incandescent lamp
- Instant 100 % light, no warm-up time
- Contains no mercury, can be thrown away with normal household waste
- UV filter

### Product features

---

- 100 % dimmable
- Perfect color rendering ( $R_a$ : 100)
- Average life: 2,000 h

## Technical data

---

### Electrical data


Rated wattage	116 W
Nominal wattage	116 W
Nominal voltage	230 V
Claimed equiv. conventional lamp power	150 W
Rated power factor $\lambda$	1.00

### Light technical data

Light color as per EN 12464-1	Warm White
Nominal luminous flux	2135 lm
Rated luminous flux	2135 lm
Color temperature	2800 K
Color rendering index Ra	100
Starting time	0.0 s
Warm-up time (60 %)	0 s
Lumen main.fact.at end of nom.life time	0.80

### Dimensions & weight

Length	94.0 mm
Overall length	97.0 mm
Diameter	55.0 mm
Light center length (LCL)	73.0 mm
Outer bulb	A55

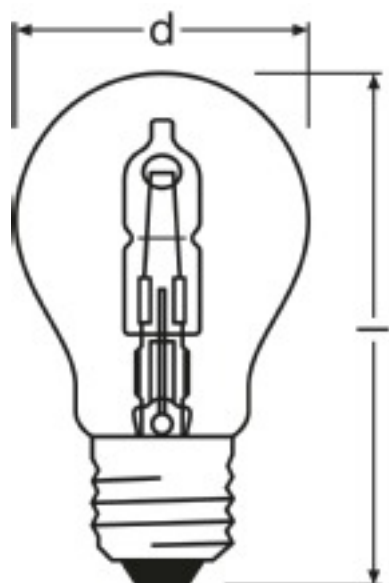

Product line drawing with letters

#### Colors & materials

Lamp mercury content	0.0 mg
Mercury-free	Yes

#### Lifespan

Nominal lamp life time	2000 h
Rated lamp life time	2000 h
Number of switching cycles	50000 <sup>1)</sup>

<sup>1)</sup> At 1 min on / 3 min off

#### Additional product data

Base (standard designation)	E27
New article	NEW

**Capabilities**

<b>Dimmable</b>	Yes
<b>Burning position</b>	Any

**Certificates & standards**

<b>EEI – Energy Label</b>	C
---------------------------	---

**Country specific categorizations**

<b>ILCOS</b>	HSGSA/C/UB-116-230-E27
<b>Order reference</b>	64548 A PRO

## References / Links

---

For an extended range for non-EU countries see

▶ [www.osram.com](http://www.osram.com)

## Disclaimer

---

Subject to change without notice. Errors and omission excepted. Always make sure to use the most recent release.