

Technical data


WS81104

Thrust washer



Needle roller bearing, thrust needle roller bearing, inner ring

VISUAL (S)

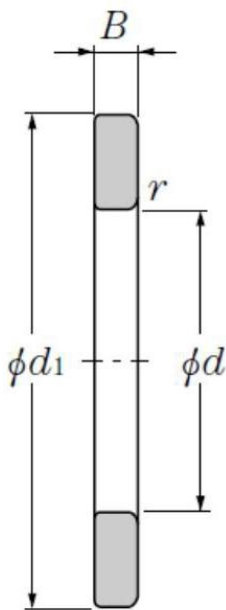

PRODUCT DEFINITION

Brand	NTN
d - Bore diameter of support washer IR - WS	20 mm
d1 - External diameter of support washer IR - WS	35 mm
B - Ring thickness	2,75 mm
rs - Min fillet radius	0,3 mm
Bearing ring (inner ring) WS mass	0,014 kg

PRODUCT PERFORMANCE

Tmin - Min operating temperature	-20 °C
----------------------------------	--------



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
 S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
 SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT PERFORMANCE	
Tmax - Max operating temperature	120 °C
ESHOPDONOTDISPLAY	
Tracepart	Oui/Yes
Reference	WS81104
Image	NRBWS_1.jpg, NRBWS_3.jpg

