



VDE TORX® screwdriver sockets 3/8"

12174 VDE




Product no. **02390045**
GTIN **4018754253630**
Model **12174 VDE T 45**



Label. 3/8 " VDE screwdriver socket L.67mm

- Properties.**
- for recessed TORX® screws
 - 3/8" internal square drive
 - VDE insulated up to 1,000 V
 - protective insulation according to IEC 60900-AC 1,000 V / DC 1,500 V
 - Chrome Alloy Steel, gun metal finish

Technical drawing.

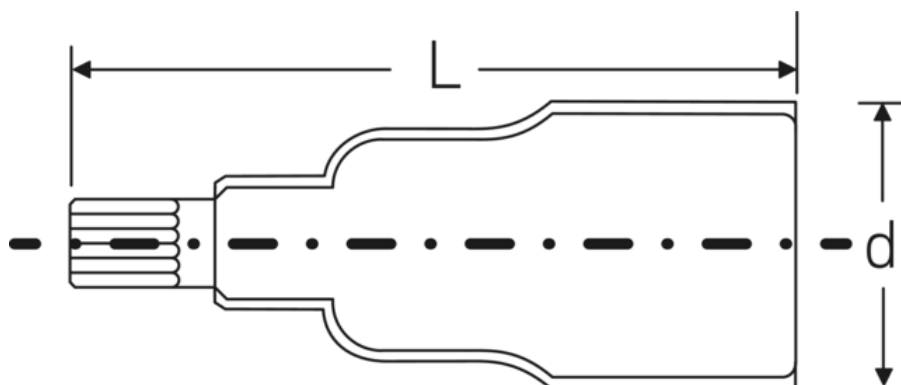

Technical attributes.

Drive profile	TORX®
Internal square drive (inch)	3/8 "
d	22,8 mm
DIN	DIN EN 60900

Logistics data.

Depth mm (IFS)	66
Width mm (IFS)	19
Height mm (IFS)	19
WEEE/ElektroG	nicht ear-pflichtig

Size of output profile	T45	Length (packed, mm)	75
Length mm (L)	67 mm	Width (packed, mm)	35
		Height (packed, mm)	35
		Volume (packed, dm ³)	0.091875 dm ³
		Art. no.	02390045
		Weight (gross, kg)	0,075
		Weight PAP (kg)	0,000
		Weight PVC (kg)	0,002
		GTIN	4018754253630
		Country of origin AWR	GERMANY
		Region of origin	Nordrhein-Westfalen
		Customs tariff no.	82042000
		Packing standard	1
		Weight	58 g

Variants.

Art. no.	Model no. (ERP)	Description	GTIN
02390020	12174 VDE T 20	3/8 " VDE screwdriver socket L.67mm	4018754253593
02390025	12174 VDE T 25	3/8 " VDE screwdriver socket L.67mm	4018754253609
02390030	12174 VDE T 30	3/8 " VDE screwdriver socket L.67mm	4018754253616
02390040	12174 VDE T 40	3/8 " VDE screwdriver socket L.67mm	4018754253623
02390045	12174 VDE T 45	3/8 " VDE screwdriver socket L.67mm	4018754253630

GTIN.

