


# OX'O ST

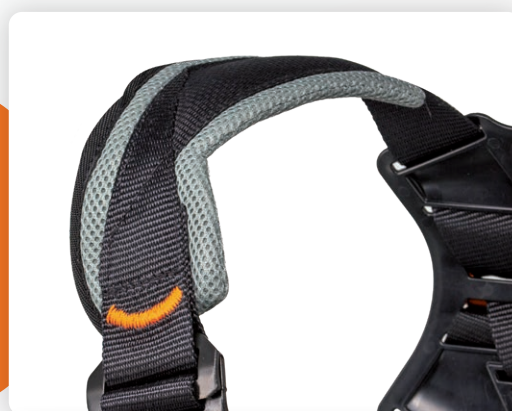

REF.  
**NUS95**

**Ergonomic full body and rescue harness**



neofeu.com

## REGULATION


2016 / 425

## CERTIFICATION

EN 361 : 2002  
EN 1497 : 2007




## TECHNOLOGIES

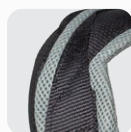

**COMFORT PAD**  
3D shoulder padding, soft and comfortable



**EASY CHECK**  
Fall indicators for quick and visual inspection

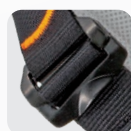

**SPEED SET**  
Quick adjustment buckles (non-opening)



**X-FLEX**  
Freedom of movement thanks to its X-shape

## TECHNICAL SPECIFICATIONS

- 1 • Main water-repellent polyester webbing 44 mm (R≥25kN)
- 2 • Shoulder and leg straps equipped with 3D padding, soft and breathable
- 3 • Shoulder straps adjusted by pulling downward and leg straps adjusted using quick-release male/female buckles in black epoxy-coated steel
- 4 • Chest strap with automatic aluminium buckle with locking indicator
- 5 • Sternal attachment point on textile loops to be connected
- 6 • Dorsal attachment point on aluminium D-ring
- 7 • Large polypropylene back plate
- 8 • User and product identification pocket
- 9 • Easily identifiable fall indicators



## DESCRIPTION

**Ergonomic** full body harness and rescue harness, **OX'O ST** is designed with an **innovative X-shape architecture** that perfectly fits the user's body shape.

This unique design ensures **an uniform distribution of forces**, reduces pressure points, and eliminates neck chafing. The **inclined leg straps** and the X-shape webbing at the waist provide **freedom of movement** and long-lasting comfort, even during intensive use.

Equipped with **quick-adjust buckles**, dorsal and sternal attachment points, and visible fall indicators, **OX'O ST** ensures quick donning and simplified safety inspection.

Its **reinforced and ventilated 3D fabric shoulder pads**, together with ergonomic leg straps, offer **breathable and durable comfort**.

| REFERENCES | EAN13         | SIZE  |              |              |            |              | WEIGHT  |
|------------|---------------|-------|--------------|--------------|------------|--------------|---------|
|            |               | Sizes | Chest        | Belt         | Legs       | Height       |         |
| NUS95..S   | 3760256369746 | S     | 80 - 105 cm  | 65 - 105 cm  | 45 - 65 cm | 155 - 175 cm | 1,10 kg |
| NUS95..ML  | 3760256369753 | M/L   | 90 - 115 cm  | 85 - 120 cm  | 50 - 75 cm | 165 - 188 cm | 1,18 kg |
| NUS95..XL  | 3760256369760 | XL    | 100 - 135 cm | 105 - 130 cm | 60 - 80 cm | 170 - 200 cm | 1,26 kg |
| NUS95..XXL | 3760256369777 | XXL   | 105 - 145 cm | 115 - 135 cm | 65 - 90 cm | 175 - 205 cm | 1,34 kg |

XXL size on request