

### Features

- Crocodile Clips
  - Can attached by solder or crimp connection
- Jaw open 0.31" (7.9mm) max
- Material: Nickel-Plated Steel
- Length: 1.97" (50 mm)
- Rating: 10 Amps

### RS PRO Crocodile Clip, Steel Contact, 10A

RS Stock No.: 0205408



RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

### Product Description

Buy this product from [www.rs-pro.com](http://www.rs-pro.com)

## Crocodile Clips



- RS alligator clips is compatible with all shrouded, unshrouded and retractable 0.16in (4mm) banana plugs and is suitable for test lead termination and other applications that require quick connect and disconnect. It can also be attached by solder or crimp connection and has nickel-plated steel material.
- This Electric Heavy Duty, General Purpose, Crocodile and Alligator Clips
- A concise offering of steel and copper alligator and crocodile clips from RS suitable for applications including grounding clips, test meters clips, battery terminal connection and many others that require a durable and hardwearing alligator or crocodile clip
- Compatible with all shrouded, unshrouded and retractable 0.16" (4mm) banana plugs

### General Specifications

Material	Nickel-Plated Steel
Product Name	Alligator Clip
Type	Alligator Clip
Insulated	No
Connection Type	Can also be attached by solder or crimp connection

Commented [波幸1]:

### Electrical Specifications

Current rating	10A
----------------	-----

### Mechanical Specifications

Jaw Opening ( $\pm 10\%$ )	0.31" (7.9mm) max
Contact Material	Nickel-Plated Steel
Insulation Material	No
Dimensions ( $\pm 10\%$ )	Overall length 1.97" (50 mm)


### Approvals

# Crocodile Clips



Standards Met	RoHS Compliant
Declarations	Reach

## Spec Drawings Diameter

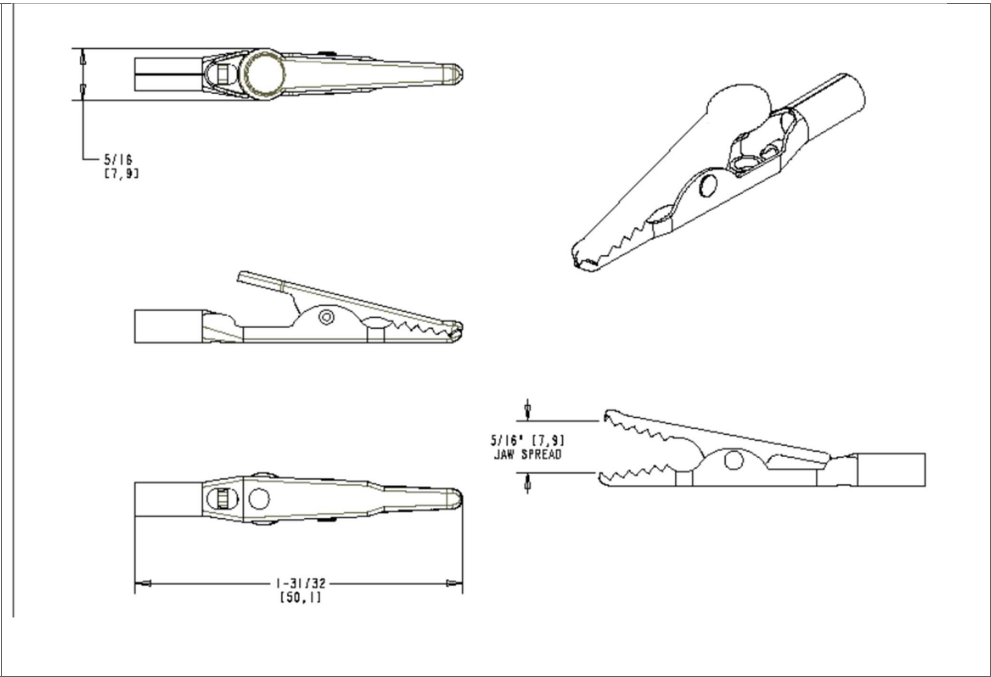

PRODUCT DIMENSION DRAWING AND ADDITIONAL INFORMATION