

819.CLO - Stainless steel flanged precision squares - Class 0





Standards:

NF E 11-103, DIN 875

Description:

- Accuracy: $\pm 5 + h/50 \mu\text{m}$ (h being height in mm).
- Stainless steel.
- Ground exterior edges and flat surfaces.

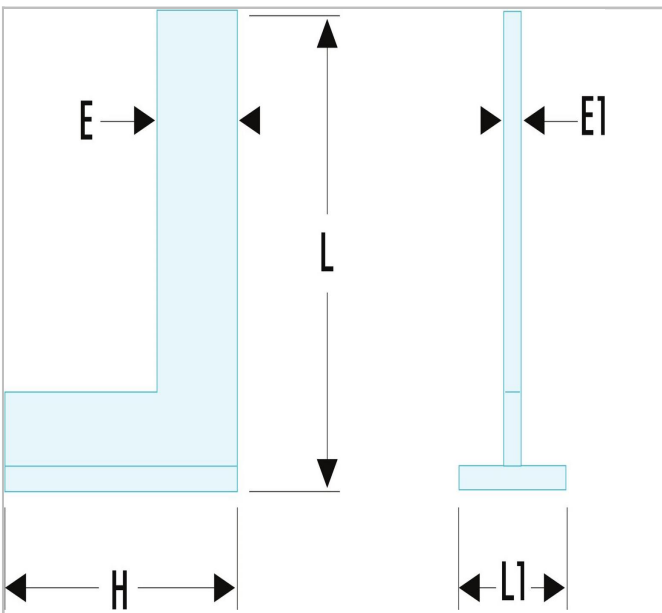

	Length L [mm]	Length L1 [mm]	Thickness E [mm]	Thickness E1 [mm]	Height H [mm]	Weight [Kg]
819.100CLO	100.0	20.0	20.0	5.0	70.0	0.28
819.150CLO	150.0	28.0	27.0	6.0	100.0	0.6
819.200CLO	200.0	32.0	31.0	7.0	130.0	1.095
819.300CLO	300.0	40.0	39.0	8.0	200.0	2.337
819.75CLO	75.0	15.0	15.0	5.0	50.0	0.175