


Features

- It's used for single and double door cabinets, especially where weather resistance is needed.

RS PRO Hinges

RS Stock No.: 0726446

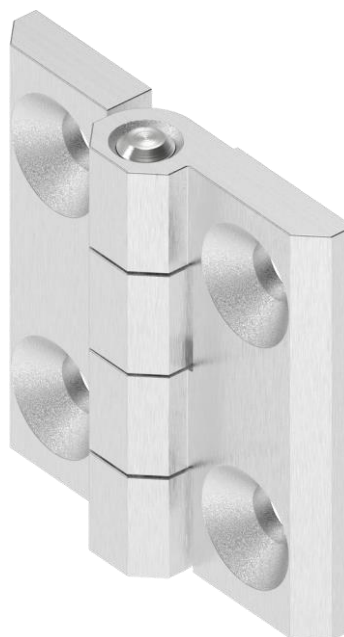

RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

This is a polished stainless steel hinge with a 180° opening. It's used for single and double door cabinets, especially where weather resistance is needed. It is fixed with screws on both door and frame and has a captive pin. This hinge allows free movement and is not self-closing.

General Specifications

Material	Polished AISI 316 stainless steel
Hinges Type	Screw-on
Closing Type	Free movement
Fixing Method	Screws
Pin Style	Fixed
Finish	Polished stainless steel
Handed	Left; Right
Colour	Metallic
Applications	Single cabinets, In-line cabinets with single or double door

Mechanical Specifications

Length	50mm
Width	50mm
Thickness	6mm
Fixing Hole Sizes	6.3x90
Radial Load	3200 N
Axial Load	3800 N
Recommended Tightening Torque	5 Nm
Weight	97g
Maximum Door Weight	To be confirmed (depends on application)
Pin Thickness	6mm
Knuckle Diameter	15mm
Pin Diameter	6mm
Opening Angle	180°
Screw Gauge	M8
Fixing Centres	36mm